


Timken® Type E Tapered Roller Bearing Housed Unit Selection

Flange: Piloted

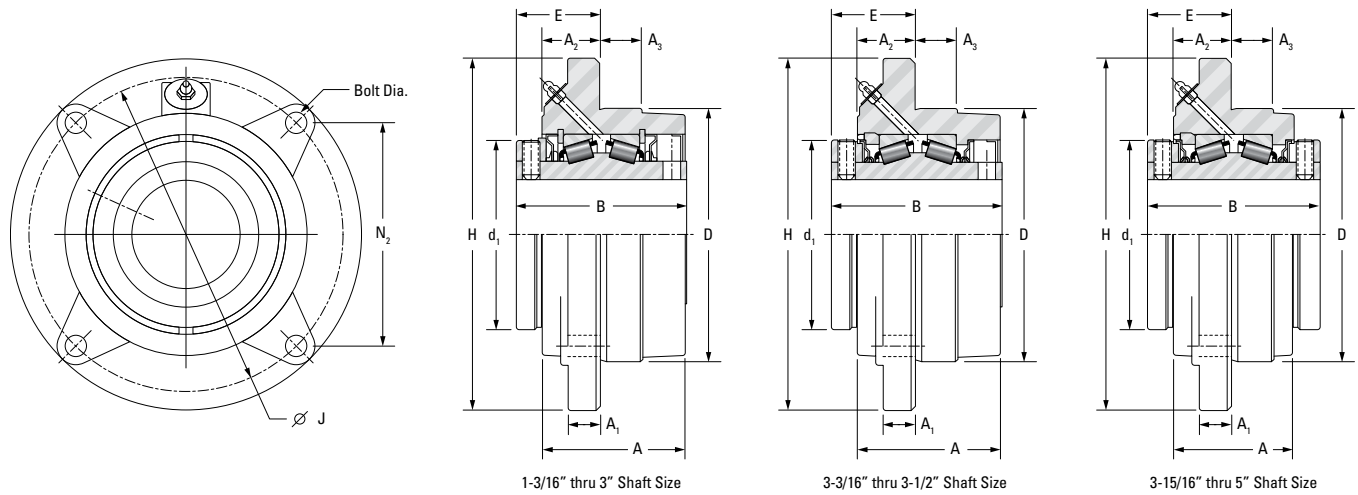

Dimensions in Inches Unless Otherwise Noted														Weight LBS (Approx)
Shaft Size	Part Number	B	H	A	N ₂	J	A ₃	Bolt Dia.	E	A ₁	D*	d ₁	A ₂	
1-3/16	E-PF-TRB-1 3/16	2-3/4	5	2-7/32	2.92	4-1/8	3/4	3/8	1-5/16	7/16	3-3/8	2-1/4	27/32	5
1-1/4	E-PF-TRB-1 1/4													5
1-3/8	E-PF-TRB-1 3/8													7
1-7/16	E-PF-TRB-1 7/16	3	5-1/4	2-15/32	3.09	4-3/8	7/8	3/8	1-1/2	1/2	3-5/8	2-3/4	1-1/32	6
35 mm	E-PF-TRB-35MM													6
1-1/2	E-PF-TRB-1 1/2													10
1-5/8	E-PF-TRB-1 5/8	3-3/8	6-1/8	2-25/32	3.62	5-1/8	1-1/16	7/16	1-9/16	1/2	4-1/4	3-3/16	1-1/32	9
1-11/16	E-PF-TRB-1 11/16													9
40 mm	E-PF-TRB-40MM													9
1-3/4	E-PF-TRB-1 3/4	3-1/2	6-3/8	2-29/32	3.80	5-3/8	1-3/16	7/16	1-9/16	9/16	4-1/2	3-7/16	1-1/32	11
1-7/8	E-PF-TRB-1 7/8													10
1-15/16	E-PF-TRB-1 15/16													10
2	E-PF-TRB-2													10
45 mm	E-PF-TRB-35MM													10
50 mm	E-PF-TRB-50MM													10
2-3/16	E-PF-TRB-2 3/16	3-3/4	7-1/8	3-3/32	4.24	6	1-3/16	1/2	1-11/16	9/16	5	3-3/4	1-3/32	14
55 mm	E-PF-TRB-55MM													14
2-1/4	E-PF-TRB-2 1/4													18
2-7/16	E-PF-TRB-2 7/16	4	7-5/8	3-5/16	4.60	6-1/2	1-5/16	1/2	1-13/16	5/8	5-1/2	4-1/16	1-3/16	18
2-1/2	E-PF-TRB-2 1/2													17
60 mm	E-PF-TRB-60MM													18
65 mm	E-PF-TRB-65MM													17
2-11/16	E-PF-TRB-2 11/16	4-1/2	8-3/4	3-11/16	5.30	7-1/2	1-1/2	5/8	2	3/4	6-3/8	4-23/32	1-1/4	27
2-3/4	E-PF-TRB-2 3/4													27
2-15/16	E-PF-TRB-2 15/16													25
3	E-PF-TRB-3													25
70 mm	E-PF-TRB-70MM													27
75 mm	E-PF-TRB-75MM	5	10-1/4	4-3/16	6.10	8-5/8	1-1/4	3/4	2-7/16	15/16	7-3/8	5-1/2	1-11/16	25
3-3/16	E-PF-TRB-3 3/16													44
3-1/4	E-PF-TRB-3 1/4													44
3-7/16	E-PF-TRB-3 7/16													43
3-1/2	E-PF-TRB-3 1/2													42
80 mm	E-PF-TRB-80MM													44
85 mm	E-PF-TRB-85MM													43
90 mm	E-PF-TRB-90MM													42
3-15/16	E-PF-TRB-3 15/16	6-1/4	10-7/8	4-1/2	6.63	9-3/8	1-1/2	3/4	2-11/16	1	8-1/8	6	1-13/16	59
4	E-PF-TRB-4													58
100 mm	E-PF-TRB-100MM													58
4-7/16	E-PF-TRB-4 7/16	6-3/4	13-1/2	4-5/8	5-7/8**	11-3/4	1-1/2	3/4**	3	1	10-1/4	6-29/64	1-15/16	110
4-1/2	E-PF-TRB-4 1/2													110
110 mm	E-PF-TRB-110MM													110
115 mm	E-PF-TRB-115MM													110
4-15/16	E-PF-TRB-4 15/16	7-1/4	14-3/4	5-1/16	6-3/8**	12-3/4	1-3/4	7/8**	2-31/32	1-1/4	11	7-29/64	1-7/8	130
5	E-PF-TRB-5													130
125 mm	E-PF-TRB-125MM													130

Note: All units have a 1/8" pipe thread grease fitting * +.000 / -.002 ** 6 holes equally spaced (chordal spacing shown)

Note: 1-3/16 to 3-1/2 utilize one collar; 3-15/16 to 5 utilize two collars