

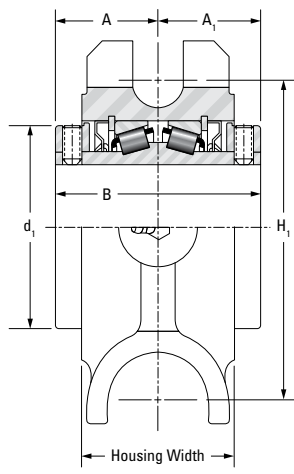


Timken® Type E Tapered Roller Bearing Housed Unit Selection

Take Up: Top Angle

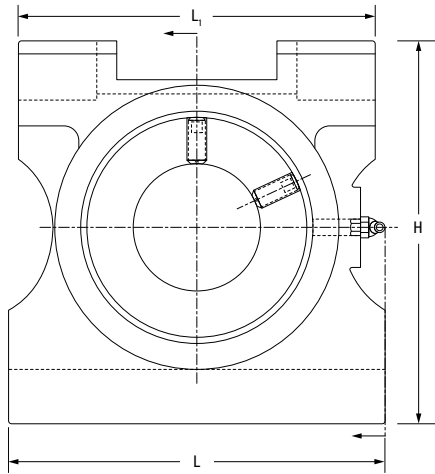

1-3/16" thru 3" Shaft Size

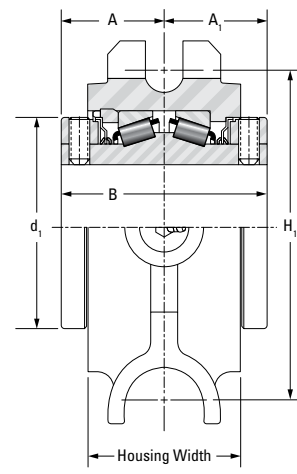

3-3/16" thru 4" Shaft Size

Dimensions in Inches Unless Otherwise Noted											Weight LBS (Approx)
Shaft Size	Part Number	B	H ₁	H	d ₁	A	A ₁	Housing Width	L	L ₁	
1-3/4	E-TTU-TRB-1 3/4	3-1/2	5-3/16	6-3/8	3-7/16	1-3/4	1-3/4	2-9/16	6-1/2	6	14
1-7/8	E-TTU-TRB-1 7/8										14
1-15/16	E-TTU-TRB-1 15/16										14
2	E-TTU-TRB-2										14
45 mm	E-TTU-TRB-45MM										14
50 mm	E-TTU-TRB-50MM	3-3/4	5-13/16	6-7/8	3-3/4	1-7/8	1-7/8	2-9/16	6-3/4	7	14
2-3/16	E-TTU-TRB-2 3/16										16
55 mm	E-TTU-TRB-55MM										16
2-1/4	E-TTU-TRB-2 1/4										21
2-7/16	E-TTU-TRB-2 7/16										21
2-1/2	E-TTU-TRB-2 1/2	4	6-1/4	7-7/16	4-1/16	2	2	3	7-1/2	7	21
60 mm	E-TTU-TRB-60MM										21
65 mm	E-TTU-TRB-65MM										21
2-11/16	E-TTU-TRB-2 11/16										21
2-3/4	E-TTU-TRB-2 3/4										29
2-15/16	E-TTU-TRB-2 15/16	4-1/2	7-3/16	8-5/16	4-23/32	2-1/4	2-1/4	3	8-1/2	8	29
3	E-TTU-TRB-3										29
70 mm	E-TTU-TRB-70MM										29
75 mm	E-TTU-TRB-75MM										29
3-3/16	E-TTU-TRB-3 3/16										43
3-1/4	E-TTU-TRB-3 1/4	5	8-5/16	9-5/8	5-1/2	2-1/2	2-1/2	3-3/4	9-1/2	9	43
3-7/16	E-TTU-TRB-3 7/16										42
3-1/2	E-TTU-TRB-3 1/2										42
80 mm	E-TTU-TRB-80MM										43
85 mm	E-TTU-TRB-85MM										42
90 mm	E-TTU-TRB-90MM	6-1/4	9-1/16	11	6	3-1/8	3-1/8	4-3/4	11	10-1/2	42
3-15/16	E-TTU-TRB-3 15/16										62
4	E-TTU-TRB-4										62
100 mm	E-TTU-TRB-100MM										62

Note: All units have a 1/8" pipe thread grease fitting