


Timken® Type E Tapered Roller Bearing Housed Unit Selection

Take Up: Wide Slot

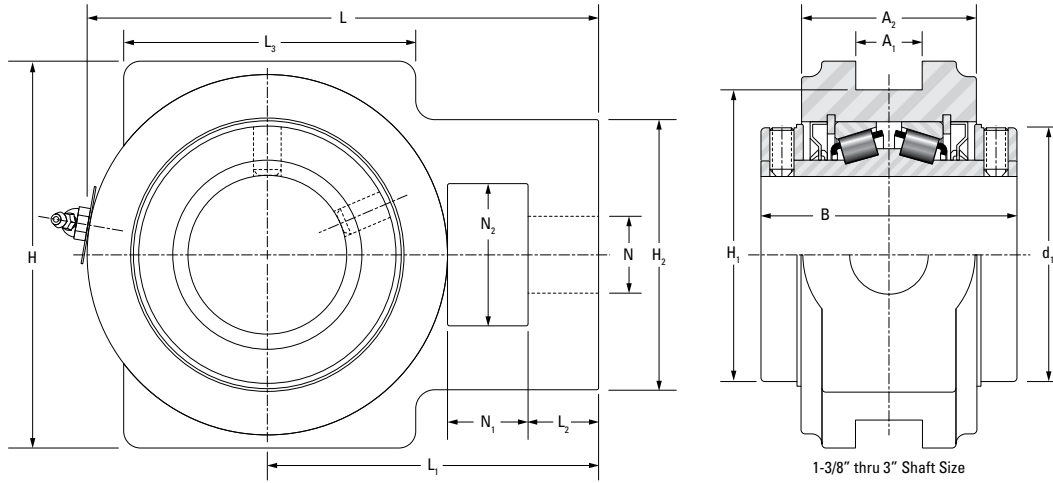

Dimensions in Inches Unless Otherwise Noted																Weight LBS (Approx)
Shaft Size	Part Number	B	L	A ₁	L ₃	L ₁	N	L ₂	N ₁	H ₂	N ₂	d ₁	H ₁	H	A ₂	
1-3/8	E-TU-TRB-1 3/8	3	5-3/32	17/32	2-3/4	3-7/32	3/4	11/16	5/8	2-7/16	1-7/16	2-3/4	3-1/2	4-1/8	2-1/16	8
1-7/16	E-TU-TRB-1 7/16															8
1-1/2	E-TU-TRB-1 1/2															10
35 mm	E-TU-TRB-35MM															8
1-5/8	E-TU-TRB-1 5/8	3-3/8	6	11/16	3-1/4	3-13/16	1	15/16	3/4	3-5/16	1-15/16	3-3/16	4	4-3/4	2-5/16	10
1-11/16	E-TU-TRB-1 11/16															10
1-3/4	E-TU-TRB-1 3/4															12
40 mm	E-TU-TRB-40MM															10
1-7/8	E-TU-TRB-1 7/8	3-1/2	6-5/16	11/16	3-3/4	3-15/16	1	15/16	3/4	3-5/16	1-15/16	3-7/16	4	4-3/4	2-7/16	12
1-15/16	E-TU-TRB-1 15/16															12
2	E-TU-TRB-2															12
45 mm	E-TU-TRB-45MM															12
50 mm	E-TU-TRB-50MM	3-3/4	7-1/8	13/16	3-3/4	4-5/8	1-1/8	1	1-1/4	3-7/8	2-1/4	3-3/4	4-1/2	5-1/4	2-9/16	12
2-3/16	E-TU-TRB-2 3/16															16
2-1/4	E-TU-TRB-2 1/4															21
55 mm	E-TU-TRB-55MM															16
2-7/16	E-TU-TRB-2 7/16	4	7-13/16	1-1/16	4-1/2	5-1/16	1-1/4	1-1/16	1-1/4	4-1/4	2-1/2	4-1/16	5-1/8	6	2-3/4	21
2-1/2	E-TU-TRB-2 1/2															21
2-11/16	E-TU-TRB-2 11/16															30
60 mm	E-TU-TRB-60MM															21
65 mm	E-TU-TRB-65MM	4-1/2	9-1/8	1-13/16	4-3/4	5-7/8	1-1/2	1-1/8	1-1/2	4-7/8	2-3/4	4-23/32	5-15/16	6-3/4	3	21
2-3/4	E-TU-TRB-2 3/4															30
2-15/16	E-TU-TRB-2 15/16															30
3	E-TU-TRB-3															30
70 mm	E-TU-TRB-70MM	4-1/2	9-1/8	1-13/16	4-3/4	5-7/8	1-1/2	1-1/8	1-1/2	4-7/8	2-3/4	4-23/32	5-15/16	6-3/4	3	30
75 mm	E-TU-TRB-75MM															30

Note: All units have a 1/8" pipe thread grease fitting